
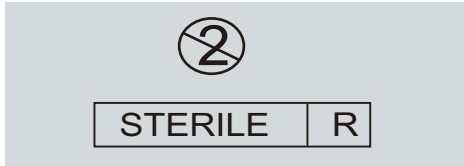


3:Dimensions (Unit: mm)

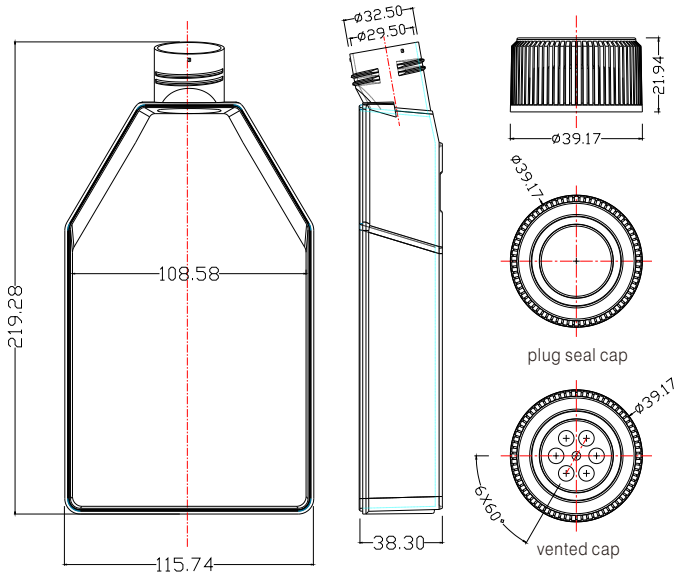

VWR® 600mL Non-treated Tissue Culture Flasks

Description: 600ML, Non-treated, w/plug seal cap, Sterilized
600ML, Non-treated, w/vent cap, Sterilized

Purpose: For use in applications where cell attachment is not desired

Materials

Flask: GPPS (General polystyrene) Color: Clear

Cap: HDPE(High Density Polyethylene) Color: Purple 259

Membrane: 0.22µm Hydrophobic PP (Only use for Vented Cap)

- Features
- Temperature: -20°C~+50°C
 - Sterilation: sterilized by gamma irradiation SAL10⁶(ISO11137)
 - Non-pyrogenic
 - Bulk packed in zip-Lock bag
 - Autoclavability: No
 - Working volume: 400 ml
 - Growth area: 182.0 cm2
 - Every product is printed with a batch number for traceability
 - Shelf Life: 3 years after month of production

VWR® 600ml Non-treated Tissue Culture Flasks

VWR EU Cat. No.	VWR NA Cat. No.	Description	Sterile	Qty/Bag	Qty/Pk	Qty/Case
734-2789	10861-578	600ML Tissue Culture Flask, Non-treated, w/plug seal cap, Sterilized	Yes	5	20	40
734-2790	10861-580	600ML Tissue Culture Flask, Non-treated, w/vent cap, Sterilized	Yes	5	20	40



Purpose: For use in applications where cell attachment is not desired

Flask: GPPS (General polystyrene) Color: Clear

Membrane: 0.22µm Hydrophobic PP (Only use for Vented Cap)

- Temperature: -20°C~+50°C
- Sterilization: sterilized by gamma irradiation SAL10⁻⁶(ISO11137)
- Non-pyrogenic
- Bulk packed in zip-Lock bag
- Autoclavability: No
- Working volume: 800 ml
- Growth area: 300.0 cm²
- Every product is printed with a batch number for traceability
- Shelf Life: 3 years after month of production

VWR® 850ml Non-treated Tissue Culture Flasks

VWR EU Cat. No.	VWR NA Cat. No.	Description	Sterile	Qty/Bag	Qty/Pk	Qty/Case
734-2791	10861-582	850ML Tissue Culture Flask, Non-treated, w/plug seal cap, Sterilized	Yes	3	9	18
734-2792	10861-584	850ML Tissue Culture Flask, Non-treated, w/vent cap, Sterilized	Yes	3	9	18



Prices and product details are current when published; subject to change without notice. | Certain products may be limited by federal, state, provincial, or local regulations. | VWR makes no claims or warranties concerning sustainable/green products. Any claims concerning sustainable/green products are the sole claims of the manufacturer and not those of VWR International, LLC. All prices are in US dollars unless otherwise noted. Offers valid in US and Canada, void where prohibited by law or company policy, while supplies last. | VWR, the VWR logo and variations on the foregoing are registered (®) or unregistered trademarks and service marks of VWR International, LLC and its related companies. All other marks referenced are registered by their respective owner(s). | Visit vwr.com to view our privacy policy, trademark owners and additional disclaimers. ©2017 VWR International, LLC. All rights reserved.